


前把手 单件包装, 宽度 12.2 mm

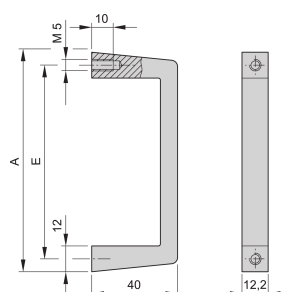

把手可以装配到插箱或 19"

面板上。可提供无色或黑色阳极氧化表面。把手将从后侧用螺栓固定。

认证



功能

静态承载能力 30 千克/对

从后面螺栓固定

技术参数

材料: 铝
产品系列: EuropacPRO
产品类型: 手柄
搭配: 插箱

Table 1/2

物料号	机架高度	完成	包装数量	手柄类型	颜色	扭矩
10501-116	1U	阳极氧化	1	直向型	银色	

物料号	机架高度	完成	包装数量	手柄类型	颜色	扭矩
10501-016	2U	阳极氧化	1	直向型	银色	
10501-004	2U	阳极氧化	1	直向型	银色	
10501-025	2U	阳极氧化	1	直向型	黑色	
10501-005	3U	阳极氧化	1	直向型	银色	2.4N • m
10501-020	3U	阳极氧化	1	斜把手	银色	2.4N • m
10501-026	3U	阳极氧化	1	直向型	黑色	2.4N • m
10501-006	4U	阳极氧化	1	直向型	银色	
10501-018	4U	阳极氧化	1	直向型	银色	2.4N • m
10501-021	4U	阳极氧化	1	斜把手	银色	2.4N • m
10501-027	4U	阳极氧化	1	直向型	黑色	
10501-007	5U	阳极氧化	1	直向型	银色	
10501-028	5U	阳极氧化	1	直向型	黑色	
10501-022	6U	阳极氧化	1	斜把手	银色	2.4N • m
10501-008	6U	阳极氧化	1	直向型	银色	2.4N • m
10501-029	6U	阳极氧化	1	直向型	黑色	2.4N • m

Table 2/2

物料号	快速发货
-----	------

10501-116	No
10501-016	No
10501-004	No
10501-025	No
10501-005	No
10501-020	No
10501-026	No
10501-006	No
10501-018	No
10501-021	No
10501-027	No
10501-007	No
10501-028	No
10501-022	No
10501-008	No
10501-029	No

其他产品详情

请单独订购装配套件。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE