


+多件式导轨, Mid-Piece Aluminium/Plastic Extrusion

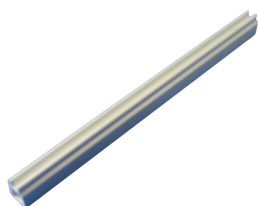

功能

中间型材，适合在 2.5 mm 宽的凹槽安装导轨

需要 2 个塑料尾端件；这些尾端件被推入中间型材两端

导轨可以卡入水平横梁（铝挤压件）或 1.5 mm 厚的板中

存储温度：-40 °C ... 130 °C

技术参数

Table 1/2

物料号	板深度	颜色	完成	槽宽	材料	包装数量
34562-822	1000mm	银色	阳极氧化	2.5	铝	1
34562-814	220mm	银色	阳极氧化	2.5	铝	1
34562-815	280mm	银色	阳极氧化	2.5	铝	1
34562-813	160mm	银色	阳极氧化	2.5	铝	1

物料号	板深度	颜色	完成	槽宽	材料	包装数量
34562-816	340mm	银色	阳极氧化	2.5	铝	1

Table 2/2			
物料号	类型	搭配	快速发货
34562-822	中段	插箱, 仪器箱, 机箱	No
34562-814	中段	插箱, 仪器箱, 机箱	No
34562-815	中段	插箱, 仪器箱, 机箱	No
34562-813	中段	插箱, 仪器箱, 机箱	No
34562-816	中段	插箱, 仪器箱, 机箱	No

其他产品详情

可能按标准包装数量 (SPQ) 交货。以单件为单位定价。

一个导轨由 1 对头部件和 1 个型材件组成。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE