


适用于 19" 机箱和插箱的安装板

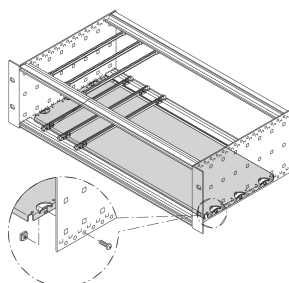

适用于重型组件或专有电子组件的安装板。适合 RatiopacPRO/-AIR、CompacPRO 和 EuropacPRO。

4,4" 型和加强型导轨不能与安装板组合使用。适用轻型（L 型）水平横梁凹槽的顶盖/底盖不能与安装板组合使用。

认证



功能

用于重组件的装配

安装板, 全宽: 安装板的宽度与插箱/系统机箱一样宽, 并固定在侧面板上

安装板, 非全宽: 通过装配条将部分宽度安装板固定到侧板

机箱板不能与 EMC 顶盖/底盖组合使用

技术参数

材料: 铝
产品类型: 安装板
搭配: 插箱

Table 1/2

物料号	机架宽度	包装数量	深度	产品系列	宽度	认证
34562-745	28HP	1	112.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS

物料号	机架宽度	包装数量	深度	产品系列	宽度	认证
34562-749	28HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-746	42HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-753	28HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-747	63HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-757	28HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-750	42HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	217.99mm	RoHS
34562-748	84HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-754	42HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-751	63HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	324.67mm	RoHS
34562-758	42HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS

物料号	机架宽度	包装数量	深度	产品系列	宽度	认证
34562-752	84HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	431.35mm	RoHS
34562-755	63HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-759	63HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-756	84HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-760	84HP	1	292.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-870	84HP	1	352.5mm	EuropacPRO	431.35mm	
34562-871	84HP	1	412.5mm	EuropacPRO	431.35mm	

Table 2/2

物料号	快速发货
34562-745	No
34562-749	No
34562-746	No
34562-753	No
34562-747	No
34562-757	No

物料号	快速发货
34562-750	No
34562-748	No
34562-754	No
34562-751	No
34562-758	No
34562-752	No
34562-755	No
34562-759	No
34562-756	No
34562-760	No
34562-870	No
34562-871	No

其他产品详情

请单独订购安装板装配套件。

应要求提供其他版本。

非全宽安装板需要固定条，请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE