


MultipacPRO 19" 机箱基本套件

该套件便于客户配置 3 种不同的顶/底盖板。

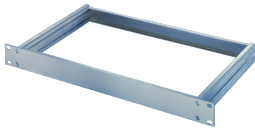

认证



功能

适用于非标准化组件 (1 ... 5 U) 和标准化组件 (1, 2 U)，符合 IEC 60297-3-105 标准

框架包括两个侧板和前/后面板

材料：铝

选择其他组件（附件）

技术参数

材料:	铝
类型:	可配置
产品系列:	MultipacPRO
EMC 屏蔽:	无（可改装）
产品类型:	插箱/机箱

Table 1/2

物料号	机架高度	深度	可用宽度	安装	符合	认证
-----	------	----	------	----	----	----

20860-201	1U	220mm	403mm	机架	IEC 60297-3-100	RoHS
20860-202	1U	280mm	403mm	机架	IEC 60297-3-100	RoHS
20860-203	1U	340mm	403mm	机架	IEC 60297-3-100	RoHS
20860-204	1U	400mm	403mm	机架	IEC 60297-3-100	
20860-205	1U	460mm	403mm	机架	IEC 60297-3-100	
20860-210	2U	220mm	403mm	机架	IEC 60297-3-100	RoHS
20860-231	4U	460mm	403mm	机架	IEC 60297-3-100	RoHS
20860-211	2U	280mm	403mm	机架	IEC 60297-3-100	RoHS
20860-212	2U	340mm	403mm	机架	IEC 60297-3-100	RoHS
20860-213	2U	400mm	403mm	机架	IEC 60297-3-100	
20860-214	2U	460mm	403mm	机架	IEC 60297-3-100	
20860-219	3U	280mm	403mm	机架	IEC 60297-3-100	RoHS
20860-220	3U	340mm	403mm	机架	IEC 60297-3-100	RoHS
20860-221	3U	400mm	403mm	机架	IEC 60297-3-100	RoHS
20860-228	4U	280mm	403mm	机架	IEC 60297-3-100	RoHS
20860-222	3U	460mm	403mm	机架	IEC 60297-3-100	RoHS
20860-229	4U	340mm	403mm	机架	IEC 60297-3-100	RoHS

20860-230	4U	400mm	403mm	机架	IEC 60297-3-100	RoHS
20860-240	5U	460mm	403mm	机架	IEC 60297-3-100	RoHS

Table 2/2	
物料号	快速发货
20860-201	No
20860-202	No
20860-203	No
20860-204	No
20860-205	No
20860-210	No
20860-231	No
20860-211	No
20860-212	No
20860-213	No
20860-214	No
20860-219	No
20860-220	No
20860-221	No

物料号	快速发货
20860-228	No
20860-222	No
20860-229	No
20860-230	No
20860-240	No

其他产品详情

请单独订购安装板、盖板和底板、把手、伸缩滑轨。

尺寸 h = 净安装高度 = H - 8.1 mm，b = 净安装宽度 = 403 mm。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE