


MultipacPRO 安装板

安装板专为安装变压器等重型组件设计。

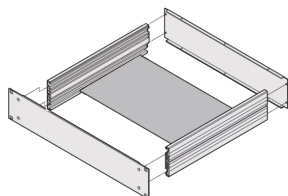

认证



功能

安装板专为重组件安装而设计, 例如, 变压器

横向螺栓内部位于 19" 机箱上

技术参数

材料: 铝
 搭配: 机箱
 产品类型: 安装板
 产品系列: MultipacPRO

Table 1/1

物料号	深度	包装数量	机架宽度	宽度	认证	快速发货
20860-107	150mm	1	84HP	402.5mm	RoHS	No
20860-112	450mm	1	84HP	402.5mm		No

物料号	深度	包装数量	机架宽度	宽度	认证	快速发货
20860-111	390mm	1	84HP	402.5mm	RoHS	No
20860-108	210mm	1	84HP	402.5mm	RoHS	No
20860-110	330mm	1	84HP	402.5mm	RoHS	No
20860-109	270mm	1	84HP	402.5mm	RoHS	No

其他产品详情

在内部安装欧式电路板时，也可以固定安装板。

如果使用安装板，净安装高度将降低至少 2.5 mm。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE