


# Novastar 19" 角轨

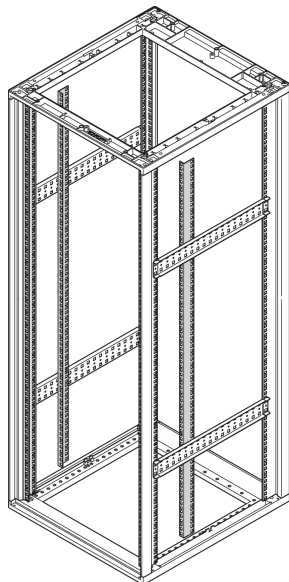

Novastar 19" 面板/滑轨安装套件，承载能力 400 kg，可确保轻松将 19" 组件安装至埋深构件。

## 认证



## 功能

用于 19" 组件嵌入式安装

用于安装到深度支撑上（25 mm间隔）

承载能力 400 千克

## 技术参数

产品类型： 滑动安装座

材料： 钢

| Table 1/2 |      |      |     |          |      |           |
|-----------|------|------|-----|----------|------|-----------|
| 物料号       | 机架高度 | 包装数量 | 颜色  | 颜色代码     | 完成   | 高度        |
| 27230-172 | 6U   | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 267.1mm   |
| 27230-173 | 9U   | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 400.45mm  |
| 27230-174 | 12U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 533.8mm   |
| 27230-175 | 16U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 711.6mm   |
| 27230-176 | 20U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 889.4mm   |
| 27230-177 | 25U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 1111.65mm |
| 27230-197 | 29U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 1291mm    |
| 27230-178 | 34U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 1511.7mm  |
| 27230-179 | 38U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 1689.5mm  |
| 27230-180 | 43U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 1911.75mm |
| 27230-181 | 47U  | 2    | 暗灰色 | RAL 7021 | 粉末涂层 | 2089.55mm |

| Table 2/2 |      |      |      |
|-----------|------|------|------|
| 物料号       | 包装单位 | 认证   | 快速发货 |
| 27230-172 | 对    | RoHS | No   |
| 27230-173 | 对    | RoHS | No   |
| 27230-174 | 对    | RoHS | No   |
| 27230-175 | 对    | RoHS | No   |

| 物料号       | 包装单位 | 认证   | 快速发货 |
|-----------|------|------|------|
| 27230-176 | 对    | RoHS | No   |
| 27230-177 | 对    | RoHS | No   |
| 27230-197 |      |      | No   |
| 27230-178 | 对    | RoHS | No   |
| 27230-179 | 对    | RoHS | No   |
| 27230-180 | 对    | RoHS | No   |
| 27230-181 | 对    | RoHS | No   |

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| North America                                                                                                 | Europe                                                                                                                                                                                                                                     | Asia                                                                                                                                                                                                                             | Middle East & India                                                                                                                                                                                         |
|---------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| All locations<br>+1.763.422.2661<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Straubenhardt, Germany<br>+49.7082.794.0<br>Betschdorf, France<br>+33.3.88.90.64.90<br>Warsaw, Poland<br>+48.22.209.98.35<br>Assago, Italy<br>+39.02.932.7141<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Shanghai, China<br>+86.21.2412.6943<br>Qingdao, China<br>+86.532.8771.6101<br>Singapore<br>+65.6768.5800<br>Shin-Yokohama, Japan<br>+81.45.476.0271<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Dubai, United Arab Emirates<br>+971.4.378.1700<br>Bangalore, India<br>+91.80.6715.2001<br>Istanbul, Turkey<br>+90.216.250.7374<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> |



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE