


适用于矮门的 Novastar 门铰链支架

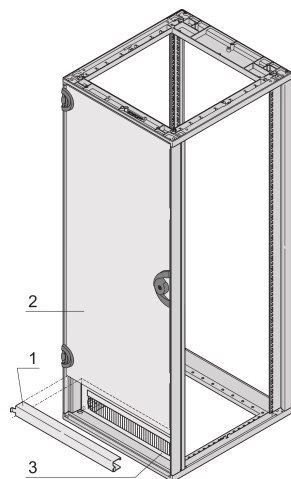

适用于矮门的门铰链支架，重型，轻型，前门或后门。

认证



功能

可安装在矮门的上方或下方（需要 1 U 装配空间）

适用于不完全覆盖机柜高度的钢门

需要 1 U 安装空间

可以使用 19" 前面板或电缆管道板（3 U 或 4 U）覆盖间隙

门铰链支架

技术参数

产品类型： 支架

Table 1/2

物料号	机架高度	宽度	材料	搭配	包装数量	颜色
-----	------	----	----	----	------	----

27230-060	1U	553mm	钢	机柜	1	暗灰色
27230-061	1U	553mm	钢		1	暗灰色
27230-098		553mm	钢	机柜	1	暗灰色

Table 2/2					
物料号	颜色代码	完成	高度	类型	快速发货
27230-060	RAL 7021	粉末涂层	44.45mm	门铰链支架	No
27230-061	RAL 7021	粉末涂层	44.45mm	门铰链支架	No
27230-098	RAL 7021	粉末涂层	44.45mm	支架	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE