


Novastar 框架, 轻型

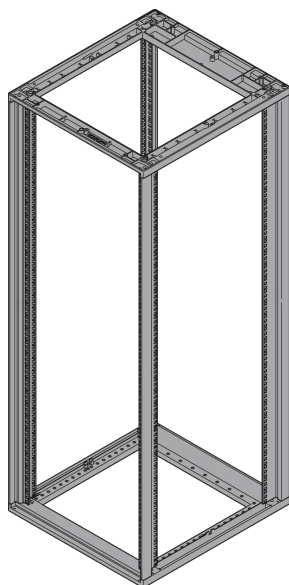

具有 200

千克静态负载能力且拥有美学设计的铝压铸框架。铝挤出型材19立柱通过螺栓连接框架

认证



功能

静态承载能力 200 千克

19" 面板 - 正面 33 mm, 背面 60 mm

铝制型材, RAL 7021, 包括接地

技术参数

静态负载: 200kg

框架材料: 铝

材料: 铝

产品类型: 机柜/机架框架

Table 1/2

物料号	机架高度	高度	宽度	深度	包装数量	颜色
28230-001	6U	323mm	553mm	500mm	1	暗灰色
28230-004	9U	456mm	553mm	500mm	1	暗灰色
28230-007	12U	589mm	553mm	500mm	1	暗灰色
28230-011	16U	767mm	553mm	500mm	1	暗灰色
28230-015	20U	945mm	553mm	500mm	1	暗灰色
28230-020	25U	1167mm	553mm	500mm	1	暗灰色
28230-029	34U	1567mm	553mm	500mm	1	暗灰色
28230-033	38U	1745mm	553mm	500mm	1	暗灰色
28230-042	47U	2145mm	553mm	500mm	1	暗灰色
28230-048	43U	1967mm	553mm	500mm	1	暗灰色
28230-054	12U	589mm	553mm	900mm	1	暗灰色
28230-055	12U	589mm	553mm	1000mm	1	暗灰色
28230-060	6U	323mm	553mm	600mm	1	暗灰色
28230-063	9U	456mm	553mm	600mm	1	暗灰色
28230-066	12U	589mm	553mm	600mm	1	暗灰色
28230-070	16U	767mm	553mm	600mm	1	暗灰色

物料号	机架高度	高度	宽度	深度	包装数量	颜色
28230-074	20U	945mm	553mm	600mm	1	暗灰色
28230-079	25U	1167mm	553mm	600mm	1	暗灰色
28230-088	34U	1567mm	553mm	600mm	1	暗灰色
28230-092	38U	1745mm	553mm	600mm	1	暗灰色
28230-097	43U	1967mm	553mm	600mm	1	暗灰色
28230-101	47U	2145mm	553mm	600mm	1	暗灰色
28230-126	12U	589mm	553mm	800mm	1	暗灰色
28230-130	16U	767mm	553mm	800mm	1	暗灰色
28230-134	20U	945mm	553mm	800mm	1	暗灰色
28230-139	25U	1167mm	553mm	800mm	1	暗灰色
28230-148	34U	1567mm	553mm	800mm	1	暗灰色
28230-152	38U	1745mm	553mm	800mm	1	暗灰色
28230-157	43U	1967mm	553mm	800mm	1	暗灰色
28230-162	47U	2145mm	553mm	800mm	1	暗灰色
28230-190	16U	767mm	553mm	900mm	1	暗灰色
28230-191	16U	767mm	553mm	1000mm	1	暗灰色
28230-194	20U	945mm	553mm	900mm	1	暗灰色

物料号	机架高度	高度	宽度	深度	包装数量	颜色
28230-195	20U	945mm	553mm	1000mm	1	暗灰色
28230-198	25U	1167mm	553mm	900mm	1	暗灰色
28230-199	25U	1167mm	553mm	1000mm	1	暗灰色
28230-202	34U	1567mm	553mm	900mm	1	暗灰色
28230-203	34U	1567mm	553mm	1000mm	1	暗灰色
28230-206	38U	1745mm	553mm	900mm	1	暗灰色
28230-207	38U	1745mm	553mm	1000mm	1	暗灰色
28230-210	43U	1967mm	553mm	900mm	1	暗灰色
28230-211	43U	1967mm	553mm	1000mm	1	暗灰色
28230-214	47U	2145mm	553mm	900mm	1	暗灰色
28230-215	47U	2145mm	553mm	1000mm	1	暗灰色
28230-024	29U	1345mm	553mm	500mm	1	暗灰色
28230-083	29U	1345mm	553mm	600mm	1	暗灰色
28230-143	29U	1345mm	553mm	800mm	1	暗灰色
28230-218	29U	1345mm	553mm	1000mm	1	暗灰色
28230-226	29U	1345mm	553mm	900mm	1	暗灰色

Table 2/2

物料号	颜色代码	完成	类型	认证	快速发货
28230-001	RAL 7021	粉末涂层	轻型	RoHS	No
28230-004	RAL 7021	粉末涂层	轻型	RoHS	No
28230-007	RAL 7021	粉末涂层	轻型	RoHS	No
28230-011	RAL 7021	粉末涂层	轻型	RoHS	No
28230-015	RAL 7021	粉末涂层	轻型	RoHS	No
28230-020	RAL 7021	粉末涂层	轻型	RoHS	No
28230-029	RAL 7021	粉末涂层	轻型	RoHS	No
28230-033	RAL 7021	粉末涂层	轻型	RoHS	No
28230-042	RAL 7021	粉末涂层	轻型	RoHS	No
28230-048	RAL 7021	粉末涂层	轻型	RoHS	No
28230-054	RAL 7021	粉末涂层	轻型	RoHS	No
28230-055	RAL 7021	粉末涂层	轻型	RoHS	No
28230-060	RAL 7021	粉末涂层	轻型	RoHS	No
28230-063	RAL 7021	粉末涂层	轻型	RoHS	No
28230-066	RAL 7021	粉末涂层	轻型	RoHS	No
28230-070	RAL 7021	粉末涂层	轻型	RoHS	No

物料号	颜色代码	完成	类型	认证	快速发货
28230-074	RAL 7021	粉末涂层	轻型	RoHS	No
28230-079	RAL 7021	粉末涂层	轻型	RoHS	No
28230-088	RAL 7021	粉末涂层	轻型	RoHS	No
28230-092	RAL 7021	粉末涂层	轻型	RoHS	No
28230-097	RAL 7021	粉末涂层	轻型	RoHS	No
28230-101	RAL 7021	粉末涂层	轻型	RoHS	No
28230-126	RAL 7021	粉末涂层	轻型	RoHS	No
28230-130	RAL 7021	粉末涂层	轻型	RoHS	No
28230-134	RAL 7021	粉末涂层	轻型	RoHS	No
28230-139	RAL 7021	粉末涂层	轻型	RoHS	No
28230-148	RAL 7021	粉末涂层	轻型	RoHS	No
28230-152	RAL 7021	粉末涂层	轻型	RoHS	No
28230-157	RAL 7021	粉末涂层	轻型	RoHS	No
28230-162	RAL 7021	粉末涂层	轻型	RoHS	No
28230-190	RAL 7021	粉末涂层	轻型	RoHS	No
28230-191	RAL 7021	粉末涂层	轻型	RoHS	No
28230-194	RAL 7021	粉末涂层	轻型	RoHS	No

物料号	颜色代码	完成	类型	认证	快速发货
28230-195	RAL 7021	粉末涂层	轻型	RoHS	No
28230-198	RAL 7021	粉末涂层	轻型	RoHS	No
28230-199	RAL 7021	粉末涂层	轻型	RoHS	No
28230-202	RAL 7021	粉末涂层	轻型	RoHS	No
28230-203	RAL 7021	粉末涂层	轻型	RoHS	No
28230-206	RAL 7021	粉末涂层	轻型	RoHS	No
28230-207	RAL 7021	粉末涂层	轻型	RoHS	No
28230-210	RAL 7021	粉末涂层	轻型	RoHS	No
28230-211	RAL 7021	粉末涂层	轻型	RoHS	No
28230-214	RAL 7021	粉末涂层	轻型	RoHS	No
28230-215	RAL 7021	粉末涂层	轻型	RoHS	No
28230-024	RAL 7021	粉末涂层	轻型		No
28230-083	RAL 7021	粉末涂层	轻型		No
28230-143	RAL 7021	粉末涂层	轻型		No
28230-218	RAL 7021	粉末涂层	轻型		No
28230-226	RAL 7021	粉末涂层	轻型		No

请单独订购门、后面板、侧面板、顶盖组件、底座、底板、机架、滑轨、脚轮或可调节支脚。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE