


盘头螺钉, Torx, 自固定

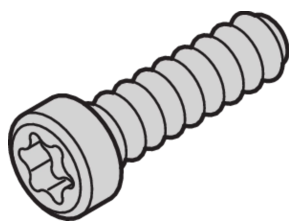

带不同公制螺纹和长度的内梅花盘头螺钉。具有 GND 接地或自固定螺纹等可选功能。

认证



功能

内梅花盘头螺钉, 自锁式

技术参数

类型: 盘头螺钉

产品类型: 螺钉

材料: 钢

Table 1/1

物料号	长度	完成	包装数量	螺纹尺寸	搭配	快速发货
24560-159	6mm	镀锌	100	M2.5	背板, 测试适配器	No
21500-039	9.3mm	镀锌	100	M2.5	前面板, H 型横梁, R 型横梁	No

最大扭矩 0.2 Nm。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE