


盘头螺钉, Torx, Self-Tapping

盘头螺钉。

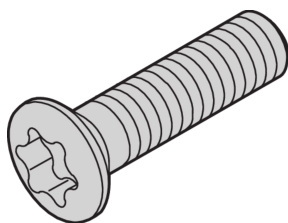

认证



功能

内梅花盘头螺钉, 自成型

用于将梯形把手安装到 PRO 框架式插件单元的前面板

技术参数

类型: 盘头螺钉

产品类型: 螺钉

材料: 钢

完成: 镀锌

Table 1/2

物料号	长度	包装数量	螺纹尺寸	产品系列	搭配	扭矩
24560-157	7.3mm	100	M2.5		前面板	
24560-141	9.3mm	100	M2.5	框架式插入单元	导轨	

物料号	长度	包装数量	螺纹尺寸	产品系列	搭配	扭矩
24560-179	10mm	100	M2.5	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO	插箱, 仪器箱, 机箱	
21101-884	6mm	100	M4	EuropacPRO	插箱	1.3N • m

Table 2/2

物料号	快速发货
24560-157	No
24560-141	No
24560-179	No
21101-884	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE