

静态梯形把手，面板单元



前面板可以装配塑料或铝型材静态梯形把手。前面板无法用导电布屏蔽。

认证



功能

前面板, 非屏蔽

前面板, 铝, 2.5 mm, 正面阳极氧化, 导电

技术参数

深度 (D): 2.5mm
 材料: 铝
 完成: 阳极氧化; 钝化
 附件类型: 前面板
 产品类型: 前面板
 类型: 把手前面板 (PIU)

Table 1/3

物料号	机架高度	机架宽度	包装数量	手柄类型	安装	正面表面处理
30847-602	3U	3HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化

物料号	机架高度	机架宽度	包装数量	手柄类型	安装	正面表面处理
30847-603	3U	4HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-604	3U	5HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-605	3U	6HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-606	3U	7HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-607	3U	8HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-608	3U	10HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-609	3U	12HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-625	6U	3HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-626	6U	4HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-627	6U	5HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-628	6U	6HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-629	6U	7HP	1	梯形，静态	正面螺钉安装	阳极氧化
30847-630	6U	8HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-631	6U	10HP	1	梯形，静态， 铝制型材	正面螺钉安装	阳极氧化
30847-632	6U	12HP	1	梯形，静态	正面螺钉安装	阳极氧化

Table 2/3

物料号	反面表面处理	边缘处理	符合	EMC 屏蔽	高度 (H)	宽度 (W)
-----	--------	------	----	--------	--------	--------


30847-602	导电	否	IEC 60297-3-101	否	128.4mm	14.9mm
30847-603	导电	否	IEC 60297-3-101	否	128.4mm	20mm
30847-604	导电	否	IEC 60297-3-101	否	128.4mm	25mm
30847-605	导电	否	IEC 60297-3-101	否	128.4mm	30.1mm
30847-606	导电	否	IEC 60297-3-101	否	128.4mm	35.2mm
30847-607	导电	否	IEC 60297-3-101	否	128.4mm	40.3mm
30847-608	导电	否	IEC 60297-3-101	否	128.4mm	50.5mm
30847-609	导电	否	IEC 60297-3-101	否	128.4mm	60.6mm
30847-625	导电	否	IEC 60297-3-101	否	261.8mm	14.9mm
30847-626	导电	否	IEC 60297-3-101	否	261.8mm	20mm
30847-627	导电	否	IEC 60297-3-101	否	261.8mm	25mm
30847-628	导电	否	IEC 60297-3-101	否	261.8mm	30.1mm
30847-629	导电	否	IEC 60297-3-101	否	261.8mm	35.2mm
30847-630	导电	否	IEC 60297-3-101	否	261.8mm	40.3mm
30847-631	导电	否	IEC 60297-3-101	否	261.8mm	50.5mm
30847-632	导电	否	IEC 60297-3-101	否	261.8mm	60.6mm

Table 3/3

物料号

快速发货

30847-602	No
30847-603	No
30847-604	No
30847-605	No
30847-606	No
30847-607	No
30847-608	No
30847-609	No
30847-625	No
30847-626	No
30847-627	No
30847-628	No
30847-629	No
30847-630	No
30847-631	No
30847-632	No

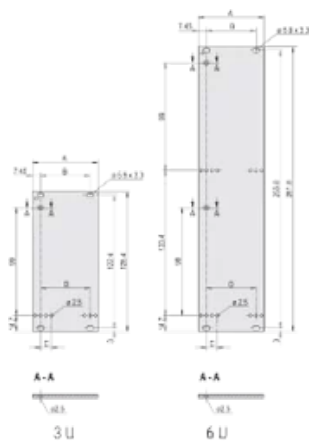

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE