


RatiopacPRO 19" 角规套件, 可改装

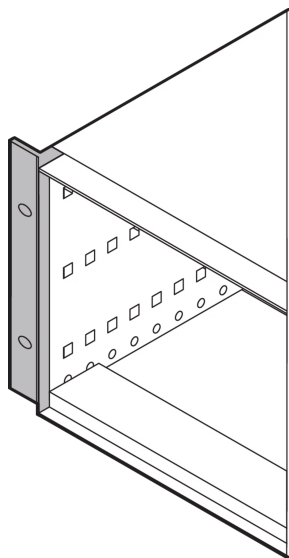

用于改装带盖条或前把手的 Ratiopac 机箱。无需拆卸机箱即可完成支架改装。

认证



功能

用于改装带盖条或前把手的机箱

技术参数

材料: 铝
产品类型: 支架
颜色代码: RAL 7016

Table 1/2

物料号	机架高度	包装数量	颜色	完成	产品系列	搭配
-----	------	------	----	----	------	----

24571-994	2U	2	浅灰色	粉末涂层	RatiopacPRO, RatiopacPRO AIR, PropacPRO, CompacPRO	仪器箱, RatiopacPRO
24571-295	3U	2	浅灰色	粉末涂层	RatiopacPRO, RatiopacPRO AIR, PropacPRO, CompacPRO	仪器箱, RatiopacPRO
24571-296	4U	2	浅灰色	粉末涂层	RatiopacPRO, RatiopacPRO AIR, PropacPRO, CompacPRO	仪器箱, RatiopacPRO
24571-298	4U	2	浅灰色	粉末涂层	RatiopacPRO AIR	仪器箱, RatiopacPRO AIR
24571-992	5U	2	浅灰色	粉末涂层	RatiopacPRO, RatiopacPRO AIR, PropacPRO, CompacPRO	仪器箱, RatiopacPRO
24571-299	5U	2	浅灰色	粉末涂层	RatiopacPRO AIR	仪器箱, RatiopacPRO AIR
24571-297	6U	2	浅灰色	粉末涂层	RatiopacPRO, RatiopacPRO AIR, PropacPRO, CompacPRO	仪器箱, RatiopacPRO
24571-300	7U	2	浅灰色	粉末涂层	RatiopacPRO AIR	仪器箱, RatiopacPRO AIR

Table 2/2

物料号	快速发货
24571-994	No

物料号	快速发货
24571-295	No
24571-296	No
24571-298	No
24571-992	No
24571-299	No
24571-297	No
24571-300	No

其他产品详情

安装到机柜或 19" 机箱中时，不得使用滑轨。

25 24

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE