


RatiopacPRO AIR 离心风扇单元

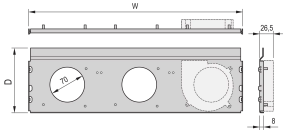

适用于 RatiopacPRO AIR 的可轻松安装的离心风扇，每风扇的风量 36 m³/h（自由送风量）。可提供 4 种宽度和 2 种深度版本，最多配备 3 个风扇。

认证



功能

滚珠轴承离心风扇

每风扇的风量 36 m³/h（自由送风量）

适合 RatiopacPRO Air 机箱（风扇单元仅需 0,5 U 高度）

仅 1/2 U 高度

通过盖板开孔排气

背面安装空间无限制

无需对机箱进行机械改造

轻松安装

技术参数

材料:	铝
搭配:	仪器箱
产品类型:	风扇
类型:	离心风扇
产品系列:	RatiopacPRO AIR

Table 1/1						
物料号	机架宽度	直流电压	气流	深度	宽度	快速发货
24572-408	28HP	12V	36m³/h	220mm	146.87mm	No
24572-405	42HP	12V	36m³/h	160mm	218mm	No
24572-409	42HP	12V	36m³/h	220mm	218mm	No
24572-406	63HP	12V	36m³/h	160mm	324.67mm	No
24572-410	63HP	12V	36m³/h	220mm	324.67mm	No
24572-407	84HP	12V	36m³/h	160mm	431.35mm	No
24572-411	84HP	12V	36m³/h	220mm	431.35mm	No
24572-404	28HP	12V	36m³/h	160mm	146.87mm	No

警告

应仔细阅读 nVent 的产品说明书并培训材料内容并使用 nVent 的产品。可访问 www.nvent.com 获取说明书。或者向你的 nVent

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE