


RatiopacPro 旋转把手装配套件

如果要安装折叠式把手，必须使用装配套件。应更换标准侧盖。

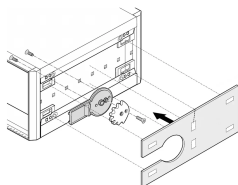

认证



功能

铝侧面板，粉末涂层，RAL 9006, 转接卡和装配材料。

技术参数

产品类型: 装配组件

搭配: 仪器箱

产品系列: RatiopacPRO; RatiopacPRO AIR

类型: 翻转式把手套装

Table 1/2

物料号	机架高度	机架宽度	深度	包装数量	完成	材料
24571-352	3U	42HP	255mm	2	粉末涂层	铝
24571-353	3U	42HP	315mm	2	粉末涂层	铝

物料号	机架高度	机架宽度	深度	包装数量	完成	材料
24571-354	3U	42HP	375mm	2	粉末涂层	铝
24571-355	3U	42HP	435mm	2	粉末涂层	铝
24571-356	3U	42HP	495mm	2	粉末涂层	铝
24571-359	4U	42HP	255mm	2	粉末涂层	铝
24571-360	4U	42HP	315mm	2	粉末涂层	铝
24571-361	4U	42HP	375mm	2	粉末涂层	铝
24571-362	4U	42HP	435mm	2	粉末涂层	铝
24571-363	4U	42HP	495mm	2	粉末涂层	铝

Table 2/2	
物料号	快速发货
24571-352	No
24571-353	No
24571-354	No
24571-355	No
24571-356	No
24571-359	No
24571-360	No

物料号	快速发货
24571-361	No
24571-362	No
24571-363	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE