


静态梯形塑料把手, 灰色

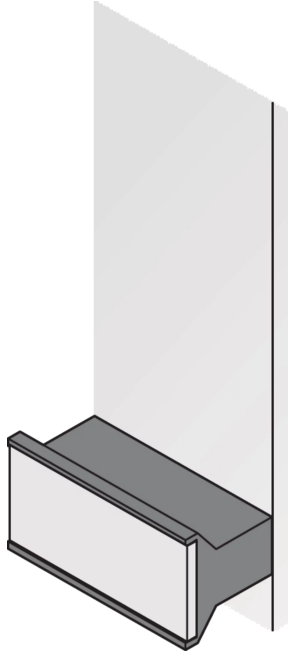

梯形灰色静态塑料把手可以安装到前面板上，用于拔出 PCB。

认证



功能

带独立识别板, Al 1.5 mm

把手, PC, UL 94 V-0

技术参数

搭配:	前面板
产品类型:	手柄
材料:	聚苯醚
类型:	静态

Table 1/2						
物料号	机架宽度	包装数量	手柄类型	可燃性等级	颜色	颜色代码
20808-062	8HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-004	10HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-067	28HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-009	40HP	1	梯形，静态	UL® 94V-0	灰色	
20808-068	42HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-012	61HP	1	梯形，静态	UL® 94V-0	灰色	
20808-003	5HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-060	6HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-061	7HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-063	9HP	1	梯形，静态	UL® 94V-0	灰色	
20808-064	12HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-065	14HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20808-066	21HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20809-294	3HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035
20809-295	4HP	1	梯形，静态	UL® 94V-0	浅灰色	RAL 7035

Table 2/2					
物料号	符合	深度 (D)	高度 (H)	宽度 (W)	快速发货

20808-062	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	39.2mm	No
20808-004	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	49.4mm	No
20808-067	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	140.8mm	No
20808-009	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			201.8mm	No
20808-068	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	212mm	No
20808-012	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			308.5mm	No
20808-003	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	24mm	No
20808-060	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	29mm	No
20808-061	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	34.1mm	No
20808-063	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			44.3mm	No
20808-064	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	59.6mm	No
20808-065	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	69.7mm	No


20808-066	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	105.2mm	No
20809-294	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	13.8mm	No
20809-295	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	18.9mm	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

不能与固定夹一起使用 (21101-239)。

图

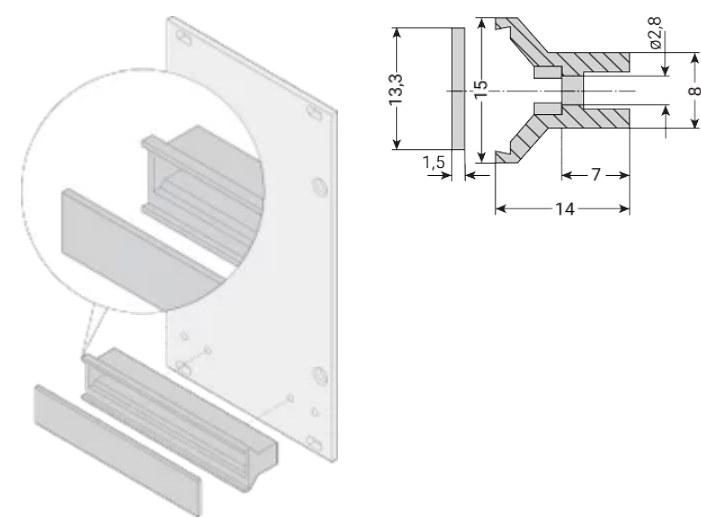

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE