


U-profile Front Panel, 屏蔽型, D-Sub 开孔

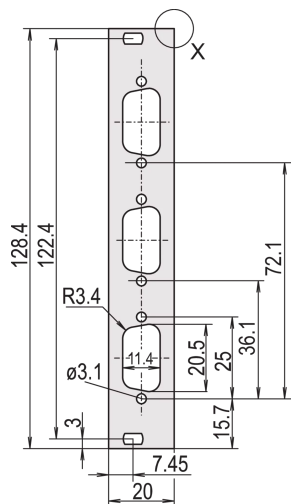

U 型前面板，带适用于 D-Sub 连接器的开孔。屏蔽型，适用于泡棉 EMC 垫片。

认证



功能

U 型, 前面板, 铝, 2.5 mm, 正面阳极氧化, 背面导电

适用 EMC 织物垫片

技术参数

深度 (D): 2.5mm

机架高度: 3U

机架宽度: 4HP

材料: 铝

完成: 阳极氧化; 钝化

附件类型: 前面板


产品类型: 前面板
 类型: 不带把手的前面板
 EMC 屏蔽: 无 (可改装)

Table 1/2

物料号	包装数量	安装	EMC 垫片类型	正面表面处理	反面表面处理	引脚数
30849-749	1	正面螺钉安装	织物	阳极氧化	导电	(1) 9
30849-750	1	正面螺钉安装	织物	阳极氧化	导电	(2) 9
30849-751	1	正面螺钉安装	织物	阳极氧化	导电	(3) 9
30849-752	1	正面螺钉安装	织物	阳极氧化	导电	(1) 15
30849-753	1	正面螺钉安装	织物	阳极氧化	导电	(2) 15
30849-754	1	正面螺钉安装	织物	阳极氧化	导电	(1) 25
30849-755	1	正面螺钉安装	织物	阳极氧化	导电	(2) 25

Table 2/2

物料号	边缘处理	符合	高度 (H)	宽度 (W)	快速发货
30849-749	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-750	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-751	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-752	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-753	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-754	否	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No

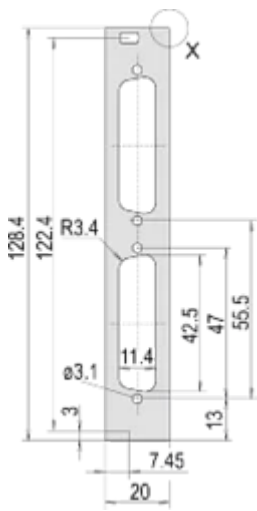

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE