


Varistar 19" 层板, 伸缩式, 30 公斤



Varistar 19"层板, 滑动式, 承载能力 30 KG, 开孔, 便于装配。

认证

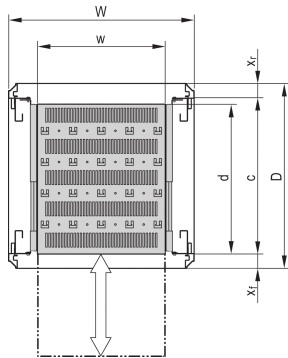

功能

完全抽出时的静态承载能力 30 千克

开孔, 用于装配扎线带

安装高度 1 U, 用于在四个 19" 面板/滑轨安装件上安装

包含伸缩滑轨

锤头穿孔, 用于固定电缆扎带

技术参数

产品类型: 货架

材料: 钢

Table 1/2

物料号	宽度	深度	包装数量	颜色	颜色代码	完成
-----	----	----	------	----	------	----

21130-342	417mm	500mm	1	暗灰色	RAL 7021	粉末涂层
22130-345	417mm	582mm	1	浅灰色	RAL 7035	粉末涂层
21130-344	417mm	700mm	1	暗灰色	RAL 7021	粉末涂层
22130-344	417mm	582mm	1	浅灰色	RAL 7035	粉末涂层
22130-343	417mm	482mm	1	浅灰色	RAL 7035	粉末涂层
21130-345	417mm	700mm	1	暗灰色	RAL 7021	粉末涂层
22130-342	417mm	382mm	1	浅灰色	RAL 7035	粉末涂层
21130-343	417mm	500mm	1	暗灰色	RAL 7021	粉末涂层

Table 2/2		
物料号	类型	快速发货
21130-342	伸缩机架，深度较浅	No
22130-345	伸缩机架	No
21130-344	伸缩机架，深度较浅	No
22130-344	伸缩机架，深度较浅	No
22130-343	伸缩机架	No
21130-345	伸缩机架	No
22130-342	伸缩机架，深度较浅	No
21130-343	伸缩机架	No

用于将伸缩滑轨装配在框架上的安装支架，请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE