


Varistar 19" 旋架饰件

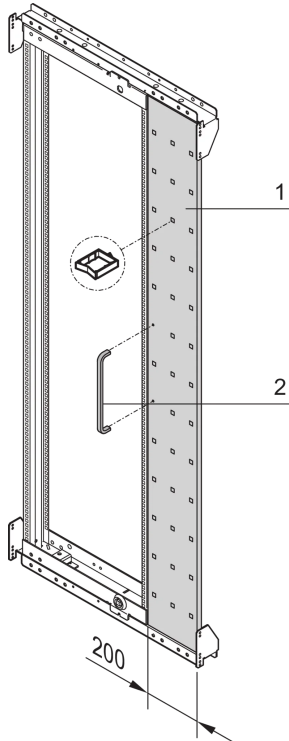

Varistar 旋架可使机架内实现最佳空间利用率。旋架配有把手。

认证



功能

包括把手和用于束线带的开孔

用于封闭 800 mm宽机架的旋架和机架立柱之间的间隙

最大旋转：120 或 160

对于150公斤承载的摇架, 出于安全原因, 建议使用限位器

锁编号 333

DIN 半圆柱锁芯的备用钥匙

技术参数

Table 1/2						
物料号	类型	材料	框架材料	颜色	颜色代码	机架高度
21130-433	旋转式	钢	钢	暗灰色	RAL 7021	29U
21130-437	旋转式	钢	钢	暗灰色	RAL 7021	47U
21130-435	旋转式	钢	钢	暗灰色	RAL 7021	38U
21130-447	旋转式	钢	钢	暗灰色	RAL 7021	47U
21130-443	旋转式	钢	钢	暗灰色	RAL 7021	29U
21130-445	旋转式	钢	钢	暗灰色	RAL 7021	38U

Table 2/2					
物料号	宽度	搭配	完成	包装数量	快速发货
21130-433	800mm	Varistar CP	粉末涂层	1	No
21130-437	800mm	Varistar CP	粉末涂层	1	No
21130-435	800mm	Varistar CP	粉末涂层	1	No
21130-447	800mm	Varistar CP	粉末涂层	2	No
21130-443	800mm	Varistar CP	粉末涂层	2	No
21130-445	800mm	Varistar CP	粉末涂层	2	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE