


Varistar 电缆理线架装配组件

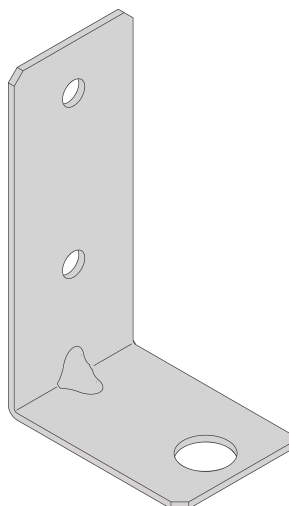

电缆转接头有助于在网络机架中连接和布设电缆。不带通用顶盖型
材的机柜需要此安装组件。

认证



功能

用于安装走线适配架的支架

技术参数

Table 1/2						
物料号	产品类型	类型	搭配	深度	长度	材料
21130-598	装配组件		通道封闭	58mm	100mm	钢
21630-168	装配组件	电缆托盘适配器	通道封闭	1000mm	1000mm	钢

物料号	产品类型	类型	搭配	深度	长度	材料
21630-169	装配组件	电缆托盘适配器	通道封闭	1100mm	1100mm	钢
21630-170	装配组件	电缆托盘适配器	通道封闭	1200mm	1200mm	钢

Table 2/2						
物料号	完成	包装数量	颜色	颜色代码	认证	快速发货
21130-598	粉末涂层	2	暗灰色	RAL 7021	RoHS	No
21630-168	粉末涂层	2	暗灰色	RAL 7021		No
21630-169	粉末涂层	2	暗灰色	RAL 7021		No
21630-170	粉末涂层	2	暗灰色	RAL 7021		No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE