


Varistar CP 19" Swing Frame Trim

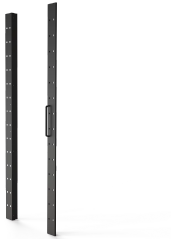

Varistar CP swing frame provides optimum space usage inside the rack. The swing frames come with handles.

功能

Includes handle and cut-out for cable eyes

To cover the gap between swing frame and cabinet upright for 800 mm wide cabinets

Maximum swing bracket: 120 or 160

For swing frame with load-carrying capacity 150 kg, a stop is recommended for security reasons

Locking no. 333

Spare key for DIN semi-profile cylinder

技术参数

产品类型: 机柜/机架框架

材料: 钢

搭配: Varistar CP

Table 1/2

物料号	机架高度	设计特征	包装数量	颜色	颜色代码	完成
21630-746	24U	非对称	1	暗灰色	RAL 7021	粉末涂层
21630-748	42U	非对称	1	暗灰色	RAL 7021	粉末涂层
21630-747	33U	非对称	1	暗灰色	RAL 7021	粉末涂层

物料号	机架高度	设计特征	包装数量	颜色	颜色代码	完成
21630-751	42U	对称设计	2	暗灰色	RAL 7021	粉末涂层
21630-750	33U	对称设计	2	暗灰色	RAL 7021	粉末涂层
21630-749	24U	对称设计	2	暗灰色	RAL 7021	粉末涂层

Table 2/2			
物料号	防护等级	类型	快速发货
21630-746	IP20	旋转式	No
21630-748	IP20	旋转式	No
21630-747	IP20	旋转式	No
21630-751	IP20	旋转式	No
21630-750	IP20	旋转式	No
21630-749	IP20	旋转式	No

其他产品详情

Varistar CP swing frame provides optimum space usage inside the rack. The swing frames come with handles.

Please purchase the grounding kit separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE