


Varistar CP 底板, 多段复合式

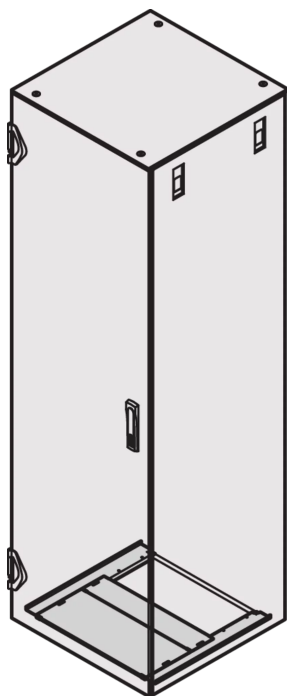

多件底板从内部组装。

请单独订购接地、盖板、毛刷条或过滤垫。

功能

覆盖底部开口

多段式底板在后面打开（向后打开 200 mm 深）, 无后开口，机柜深度为 300 mm）

技术参数

产品类型: 机柜/机架底座

材料: 钢

Table 1/2

物料号	宽度	深度	包装数量	框架	颜色	颜色代码
21630-616	600mm	600mm	1	固定式	暗灰色	RAL 7021

物料号	宽度	深度	包装数量	框架	颜色	颜色代码
21630-617	600mm	800mm	1	固定式	暗灰色	RAL 7021
21630-618	600mm	900mm	1	固定式	暗灰色	RAL 7021
21630-619	600mm	1000mm	1	固定式	暗灰色	RAL 7021
21630-620	600mm	1100mm	1	固定式	暗灰色	RAL 7021
21630-621	600mm	1200mm	1	固定式	暗灰色	RAL 7021
21630-622	800mm	600mm	1	固定式	暗灰色	RAL 7021
21630-623	800mm	800mm	1	固定式	暗灰色	RAL 7021
21630-624	800mm	900mm	1	固定式	暗灰色	RAL 7021
21630-625	800mm	1000mm	1	固定式	暗灰色	RAL 7021
21630-626	800mm	1100mm	1	固定式	暗灰色	RAL 7021
21630-627	800mm	1200mm	1	固定式	暗灰色	RAL 7021
21630-802	600mm	600mm	1	移动	暗灰色	RAL 7021
21630-803	600mm	800mm	1	移动	暗灰色	RAL 7021
21630-804	600mm	900mm	1	移动	暗灰色	RAL 7021
21630-805	600mm	1000mm	1	移动	暗灰色	RAL 7021
21630-806	600mm	1100mm	1	移动	暗灰色	RAL 7021
21630-807	600mm	1200mm	1	移动	暗灰色	RAL 7021

物料号	宽度	深度	包装数量	框架	颜色	颜色代码
21630-808	800mm	600mm	1	移动	暗灰色	RAL 7021
21630-809	800mm	800mm	1	移动	暗灰色	RAL 7021
21630-810	800mm	900mm	1	移动	暗灰色	RAL 7021
21630-811	800mm	1000mm	1	移动	暗灰色	RAL 7021
21630-812	800mm	1100mm	1	移动	暗灰色	RAL 7021
21630-813	800mm	1200mm	1	移动	暗灰色	RAL 7021

Table 2/2		
物料号	完成	快速发货
21630-616	粉末涂层	No
21630-617	粉末涂层	No
21630-618	粉末涂层	No
21630-619	粉末涂层	No
21630-620	粉末涂层	No
21630-621	粉末涂层	No
21630-622	粉末涂层	No
21630-623	粉末涂层	No
21630-624	粉末涂层	No

物料号	完成	快速发货
21630-625	粉末涂层	No
21630-626	粉末涂层	No
21630-627	粉末涂层	No
21630-802	粉末涂层	No
21630-803	粉末涂层	No
21630-804	粉末涂层	No
21630-805	粉末涂层	No
21630-806	粉末涂层	No
21630-807	粉末涂层	No
21630-808	粉末涂层	No
21630-809	粉末涂层	No
21630-810	粉末涂层	No
21630-811	粉末涂层	No
21630-812	粉末涂层	No
21630-813	粉末涂层	No

其他产品详情

多件底板从内部组装。

请单独订购接地、盖板、毛刷条或过滤垫。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE