


Varistar CP Swing Frame for 600 mm Width

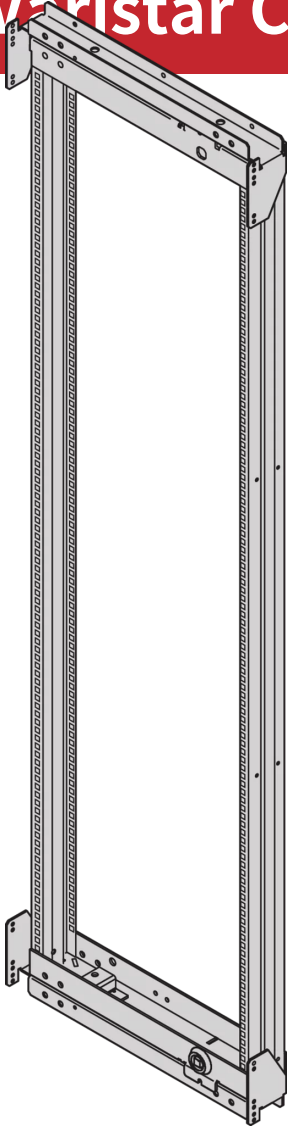

The 19 " swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° movement and flexible pivot point.

功能

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks (maximum depth 200 mm)

120° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

技术参数

宽度: 600mm
产品类型: 机柜/机架框架
材料: 钢

Table 1/2

物料号	机架高度	包装数量	颜色	颜色代码	完成	高度
21630-668	24U	1	暗灰色	RAL 7021	粉末涂层	1200mm
21630-678	47U	1	暗灰色	RAL 7021	粉末涂层	2200mm
21630-676	42U	1	暗灰色	RAL 7021	粉末涂层	2000mm
21630-674	38U	1	暗灰色	RAL 7021	粉末涂层	1800mm
21630-672	33U	1	暗灰色	RAL 7021	粉末涂层	1600mm
21630-670	29U	1	暗灰色	RAL 7021	粉末涂层	1400mm

Table 2/2

物料号	防护等级	快速发货
21630-668	IP20	No
21630-678	IP20	No
21630-676	IP20	No
21630-674	IP20	No
21630-672	IP20	No
21630-670	IP20	No

其他产品详情

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE