


Varistar CP Swing Frame for 800 mm Width

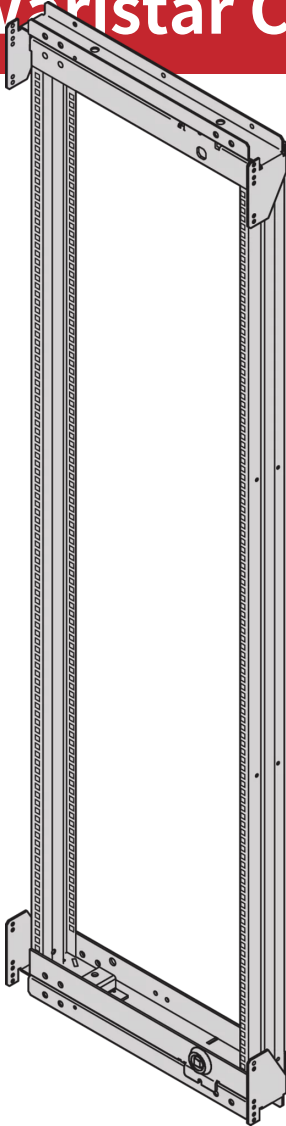

The 19 " swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° / 160° movement and flexible pivot point.

功能

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks

120° / 160° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

Usable height within the swing frame is 4U lesser than the frame height to which the swing frame is attached to.

技术参数

宽度: 800mm
产品类型: 机柜/机架框架
材料: 钢

Table 1/2

物料号	角度	机架高度	包装数量	颜色	颜色代码	完成
21630-669	120° min	24U	1	暗灰色	RAL 7021	粉末涂层
21630-671	120° min	29U	1	暗灰色	RAL 7021	粉末涂层
21630-673	120° min	33U	1	暗灰色	RAL 7021	粉末涂层
21630-675	120° min	38U	1	暗灰色	RAL 7021	粉末涂层
21630-677	120° min	42U	1	暗灰色	RAL 7021	粉末涂层
21630-679	120° min	47U	1	暗灰色	RAL 7021	粉末涂层
21630-680	160° min	24U	1	暗灰色	RAL 7021	粉末涂层
21630-681	160° min	29U	1	暗灰色	RAL 7021	粉末涂层
21630-682	160° min	33U	1	暗灰色	RAL 7021	粉末涂层
21630-683	160° min	38U	1	暗灰色	RAL 7021	粉末涂层
21630-684	160° min	42U	1	暗灰色	RAL 7021	粉末涂层
21630-685	160° min	47U	1	暗灰色	RAL 7021	粉末涂层

Table 2/2

物料号	高度	防护等级	快速发货
21630-669	1200mm	IP20	No
21630-671	1400mm	IP20	No
21630-673	1600mm	IP20	No
21630-675	1800mm	IP20	No
21630-677	2000mm	IP20	No
21630-679	2200mm	IP20	No
21630-680	1200mm	IP20	No
21630-681	1400mm	IP20	No
21630-682	1600mm	IP20	No
21630-683	1800mm	IP20	No
21630-684	2000mm	IP20	No
21630-685	2200mm	IP20	No

其他产品详情

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE