


Varistar 安装板

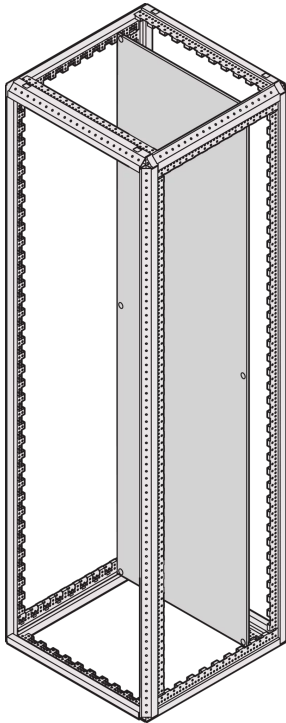

Varistar 安装板，用于安装电气组件和子组件，承载能力为 600 kg。安装板也可后装，并可增加加强支架，以增加负载能力。

认证



功能

用于安装电气部件和子组件，包括电缆

安装间距 25 mm 深度和 50 mm 高度，适用于部分高度安装

静态承载能力高达 450 千克（后部安装）

600 千克（全高），安装到后部，带额外的加强支架

强化支架可增加静态承载能力

全高时为 600 kg，安装至后部，带额外的加强支架

技术参数

产品类型: 安装板
材料: 钢

Table 1/1					
物料号	高度	宽度	包装数量	完成	快速发货
23130-405	1800mm	600mm	1	镀锌	No
23130-414	1200mm	800mm	1	镀锌	No
23130-413	1200mm	600mm	1	镀锌	No
23130-408	2000mm	800mm	1	镀锌	No
23130-406	1800mm	800mm	1	镀锌	No
23130-407	2000mm	600mm	1	镀锌	No

其他产品详情

对于非全高度安装，需要埋深构件。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE