


Varistar 滑轨

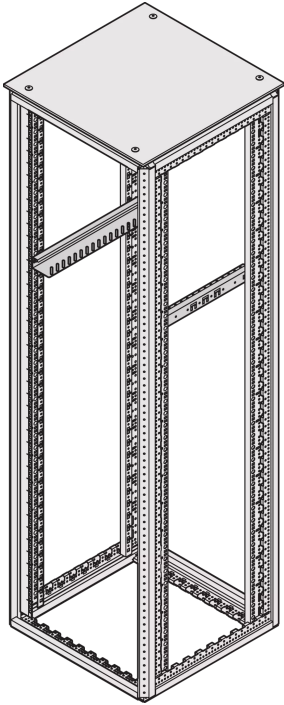

安装在4个19滑轨安装支架，承载能力25/100公斤

认证



功能

在 4 个 19 寸滑轨安装件上安装

宽度支撑表面 (48 mm)

可以 1 U 增量安装 (连接并用螺钉固定到位)

技术参数

产品类型: 滑轨

材料: 钢

Table 1/2

物料号	静态负载	包装数量	完成	高度	长度	搭配
23130-099		2	镀锌铝			Varistar CP
23130-116	100kg	2	镀锌铝	200mm	156mm	Varistar CP
23130-096	25kg	2	镀锌铝	500mm	456mm	Varistar CP
23130-097	25kg	2	镀锌铝	700mm	656mm	Varistar CP
23130-098	25kg	2	镀锌铝	740mm	699mm	Varistar CP
23130-118	100kg	2	镀锌铝	500mm	458mm	Varistar CP
23130-119	100kg	2	镀锌铝	700mm	658mm	Varistar CP
23130-120	100kg	2	镀锌铝	740mm	699mm	Varistar CP
23130-126		10	镀锌铝			Varistar CP
23130-101	25kg	10	镀锌铝	500mm	456mm	Varistar CP
23130-102	25kg	10	镀锌铝	700mm	656mm	Varistar CP
23130-103	25kg	10	镀锌铝	740mm	699mm	Varistar CP
23130-123	100kg	10	镀锌铝	500mm	458mm	Varistar CP
23130-124	100kg	10	镀锌铝	700mm	658mm	Varistar CP
23130-125	100kg	10	镀锌铝	740mm	699mm	Varistar CP

Table 2/2

物料号	包装单位	认证	快速发货
23130-099	对		No
23130-116		RoHS	No
23130-096	对	RoHS	No
23130-097	对	RoHS	No
23130-098	对	RoHS	No
23130-118		RoHS	No
23130-119		RoHS	No
23130-120		RoHS	No
23130-126		RoHS	No
23130-101		RoHS	No
23130-102		RoHS	No
23130-103		RoHS	No
23130-123		RoHS	No
23130-124		RoHS	No
23130-125		RoHS	No

其他产品详情

要在机柜中安装，必须在前后部安装 19 寸面板/角轨安装件。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE